



Cert. No. LRQ 0963008


ISO 9001



TI-S02-46
ST Issue 2


FT14浮球式蒸汽疏水阀 在低压差应用的排量图

1/2", 3/4", 1" FT14 (DN15, DN20, DN25)

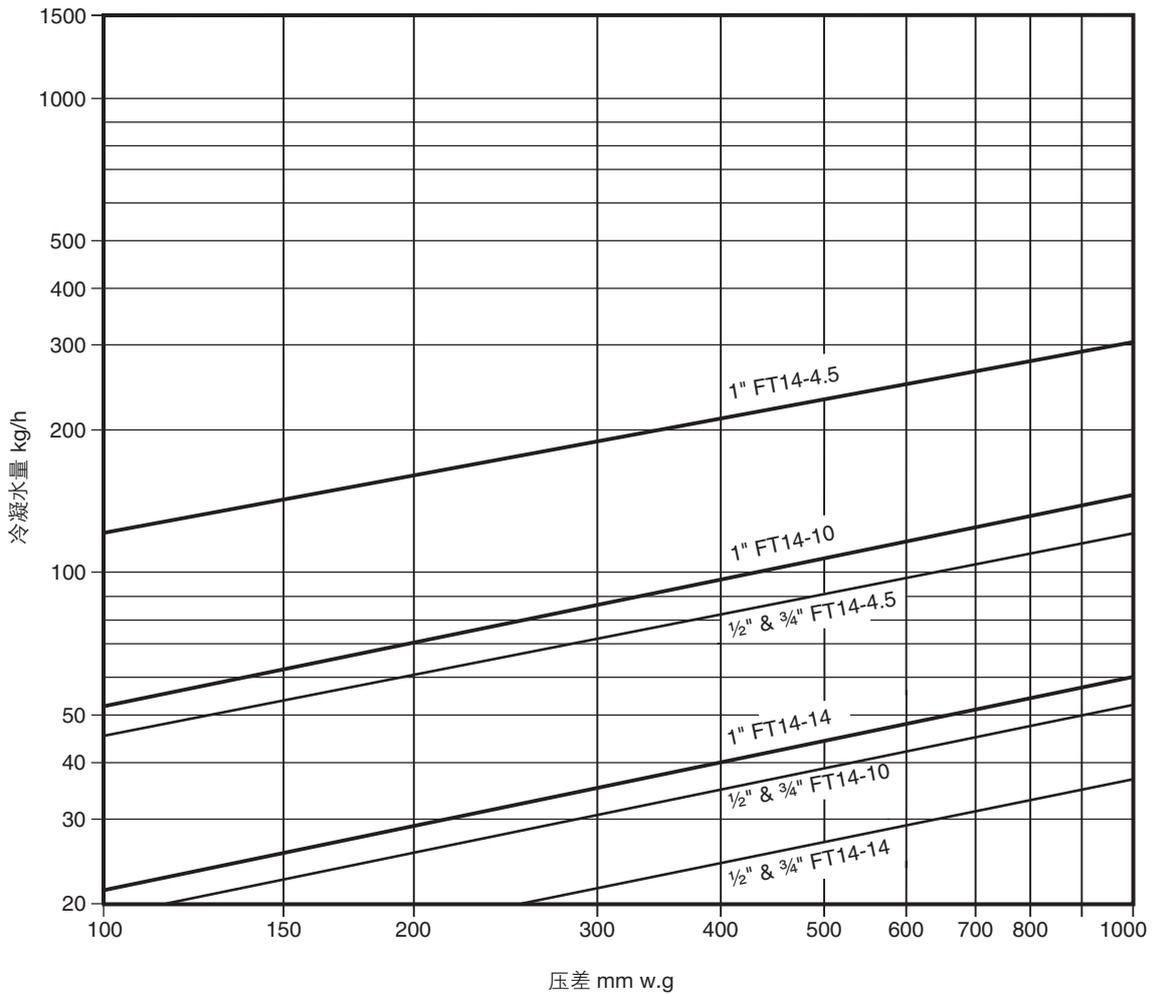

注：压差超过1000mm w.g的应用，请参考TI-S02-28

1" FT14HC (DN25 HC)
1¼", 1½" 和 2" FT14(DN40, DN50)

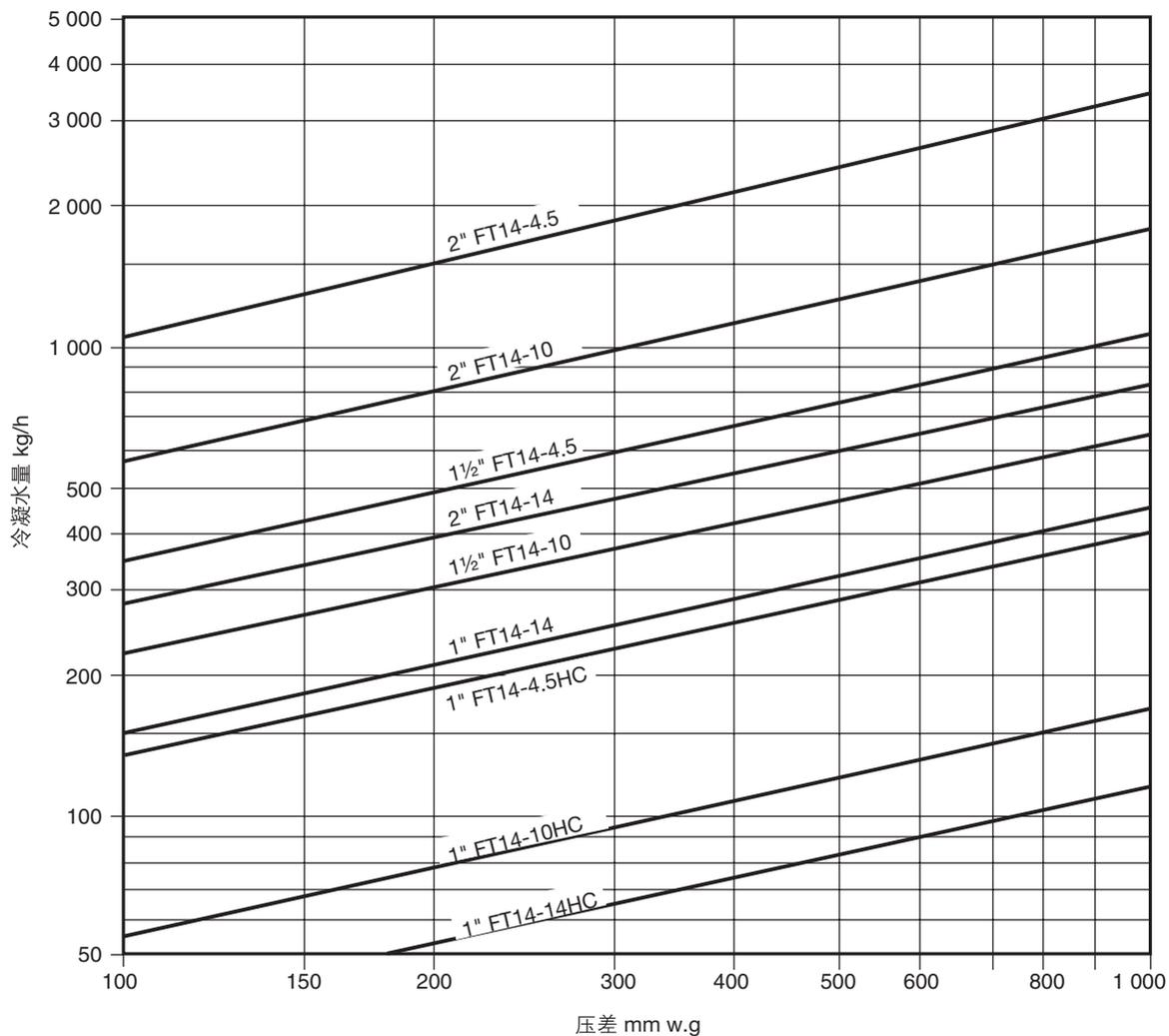

注：压差超过1000mm w.g的应用，请参考TI-S02-28