



Cert. No. LRQ 0963008

ISO 9001


spirax sarco

TI-S02-46
ST Issue 3

Capacity Charts for the FT14, FT14HC, FTGS14 and FTGS14HC


Ball Float Steam Traps at Low Differential Pressure

1/2", 3/4", 1" FT14 and FTGS14 (DN15, DN20, DN25)

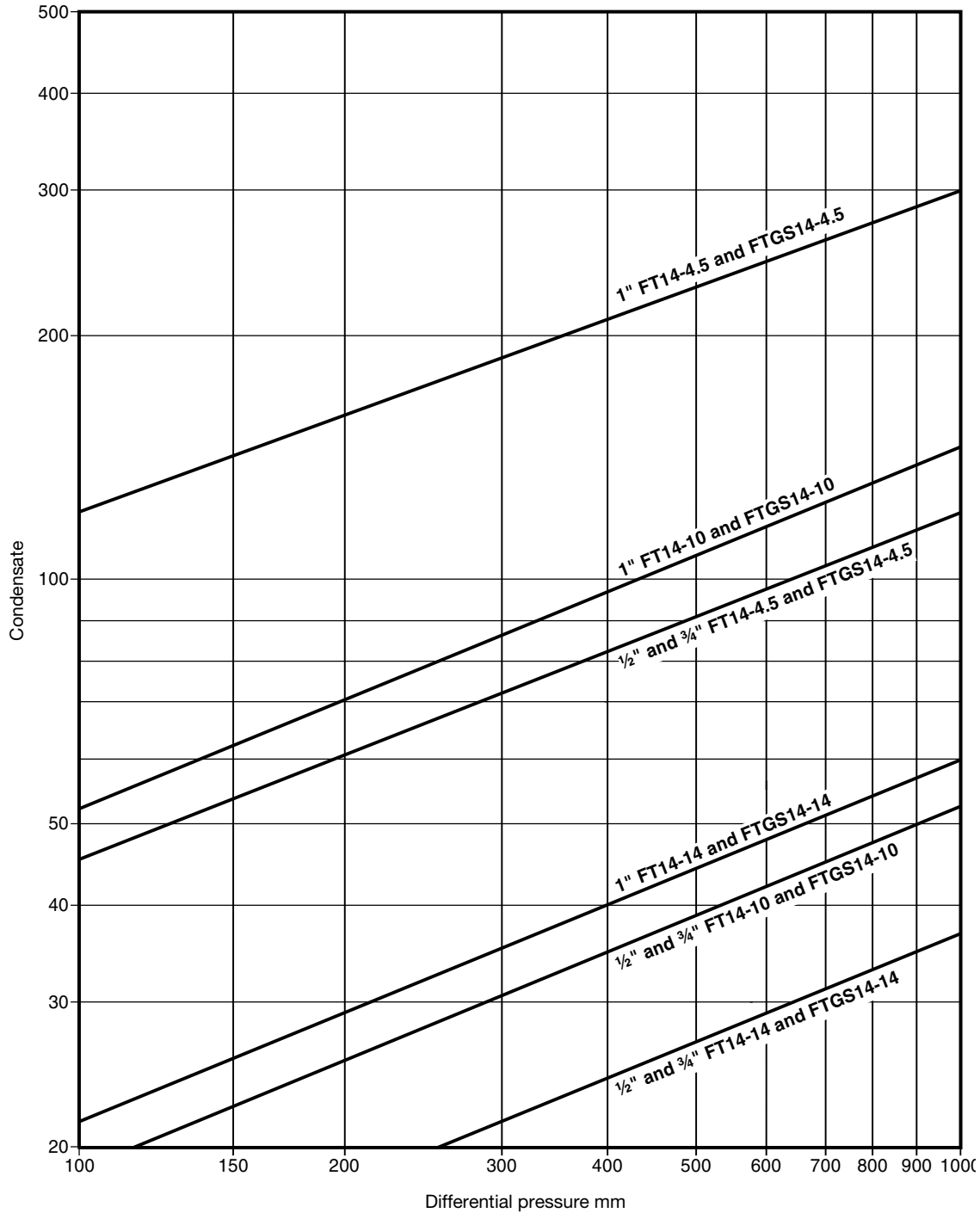

Note: For differential pressures above 1 000 mm w.g. please see TI-S02-28

**1" FT14HC and FTGS14HC
1¼", 1½" and 2" FT14 (DN40 and DN50)**

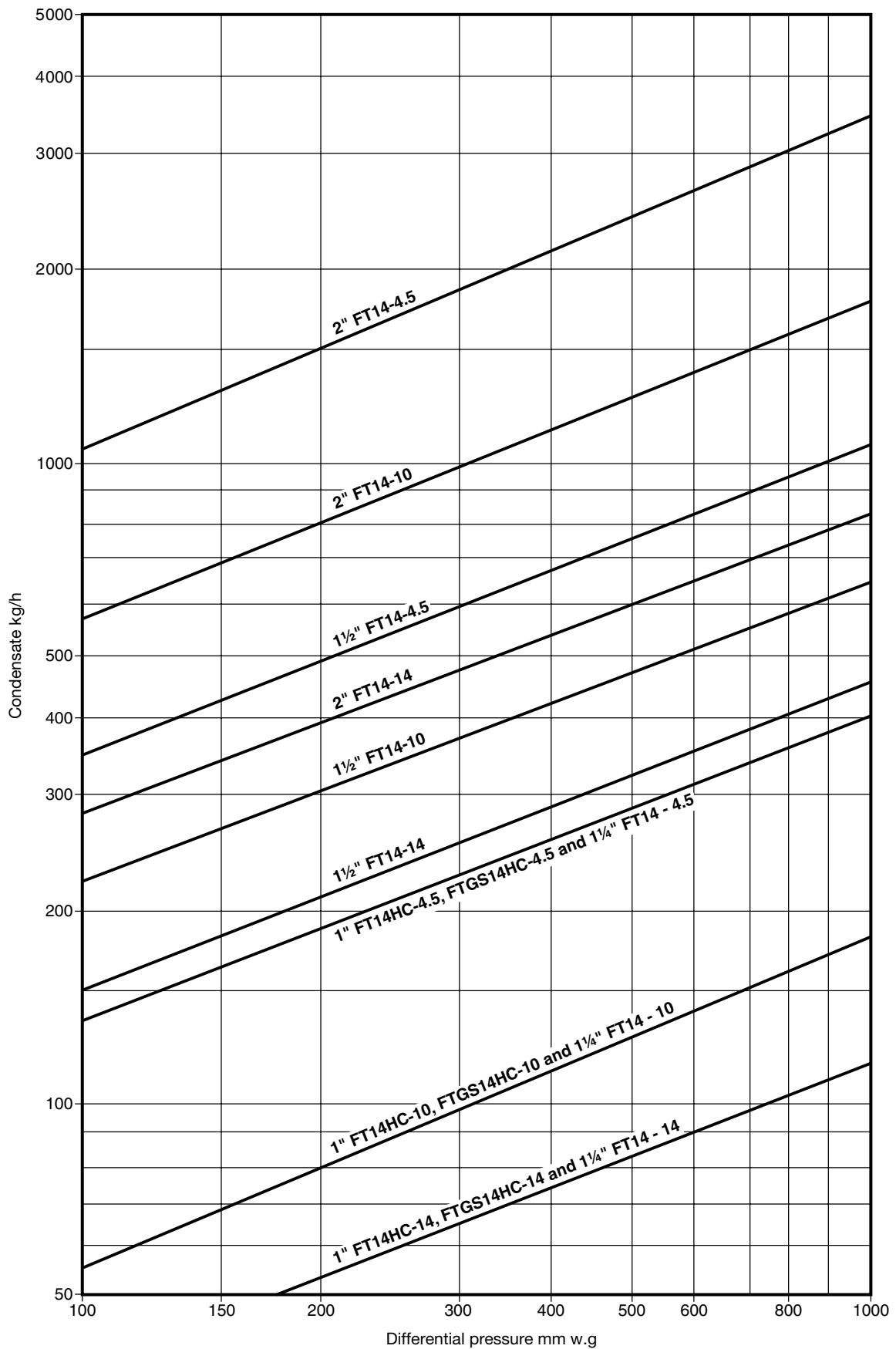

Note: For differential pressures above 1 000 mm w.g. please see TI-S02-28