

AEL3

Interruptor auxiliar

Instrucciones de instalación

Instalación de interruptores auxiliares

Para uso en ambientes normales

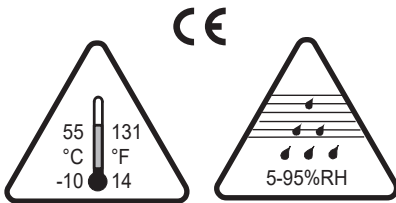


Fig. 1

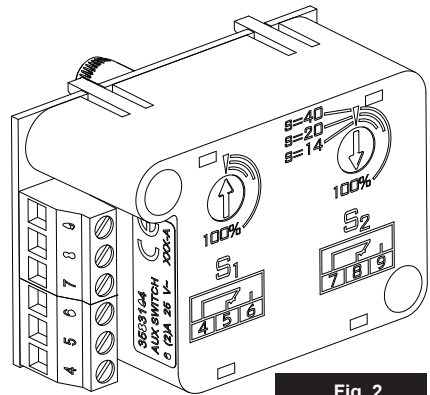


Fig. 2

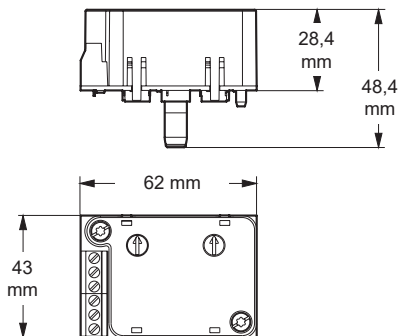


Fig. 3

	T15
	1
	3
	s24 (1x)

Fig. 4

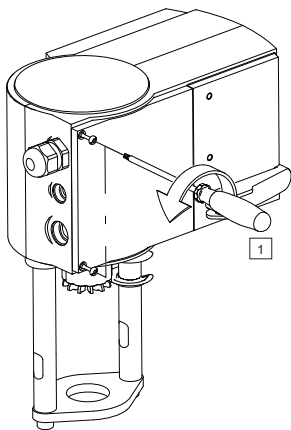


Fig. 5

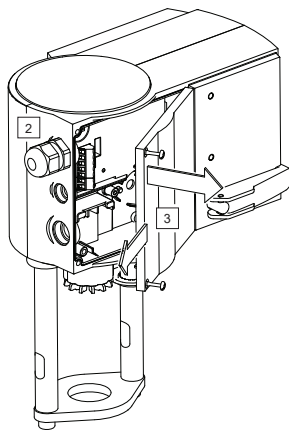


Fig. 6

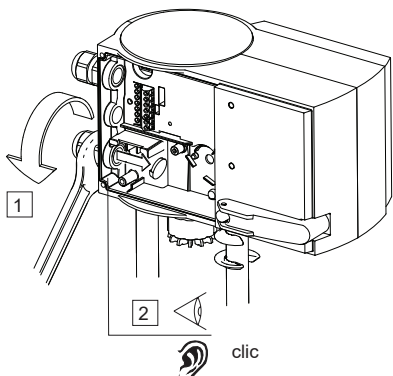


Fig. 7

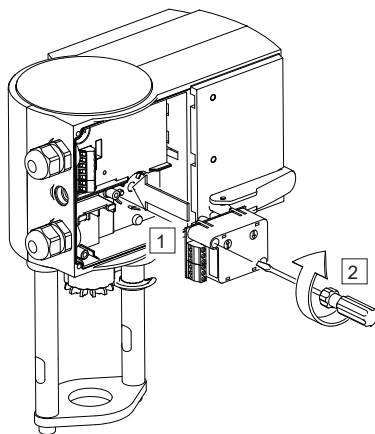


Fig. 8

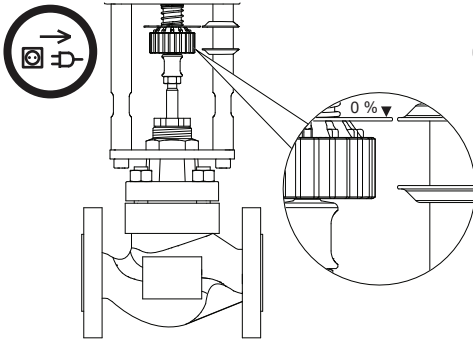


Fig. 9a

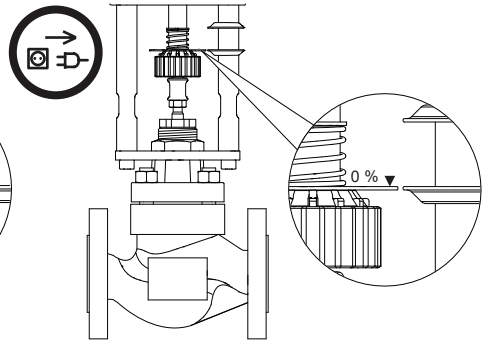


Fig. 9b

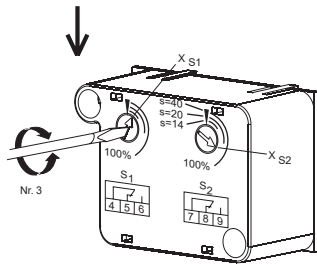


Fig. 10a

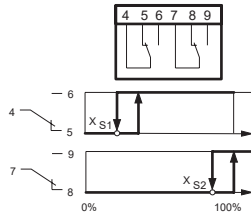


Fig. 10b

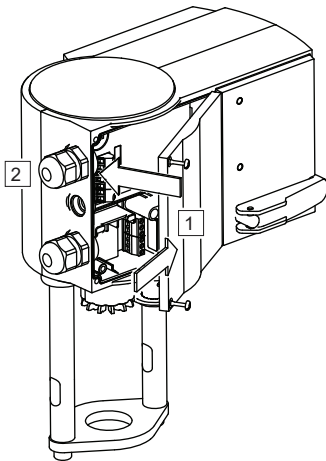
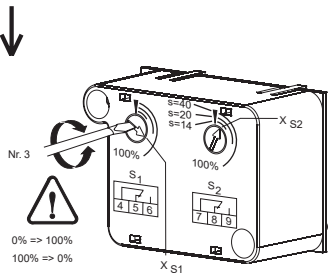


Fig. 11


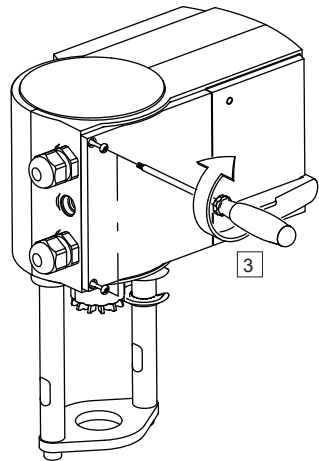


Fig. 12

Interruptor auxiliar AEL3

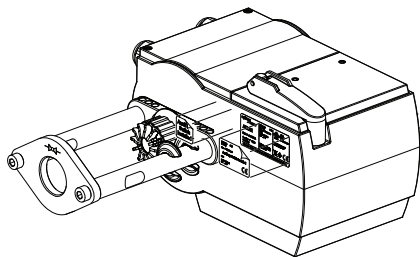

spirax sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V	 238A E7624 23FR A7F2348F232U Temperature Indicating & Regulating Equipment
	Equipment intended for connection to a Class 2 power source.	

spirax sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	---	--

24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
---	--

Nota: Solapar con la etiqueta de variante 24V ya que el interruptor auxiliar no tiene aprobación UL.

Auxiliary Switch Installed

spirax sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	---	--

Auxiliary Switch Installed

spirax sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	100-110 V- 25 VA 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	--	--

Auxiliary Switch Installed

spirax sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	230 V- 25 VA 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	--	--

Fig. 13

Interruptor auxiliar AEL3