

Interruttori ausiliari per attuatori elettrici AEL3

Istruzioni per l'installazione

Installazione dell'interruttore ausiliario di fine corsa

Da utilizzare in ambienti normali

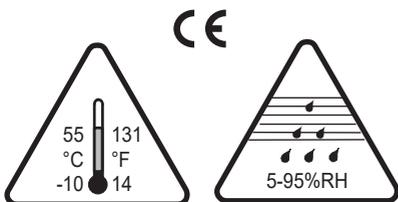


Fig. 1

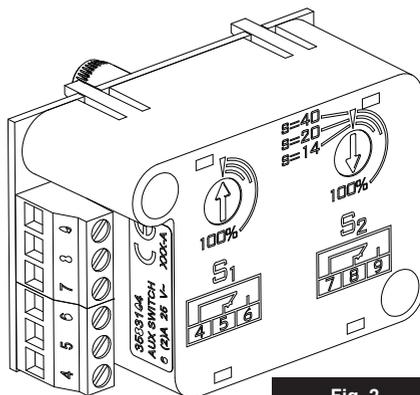


Fig. 2

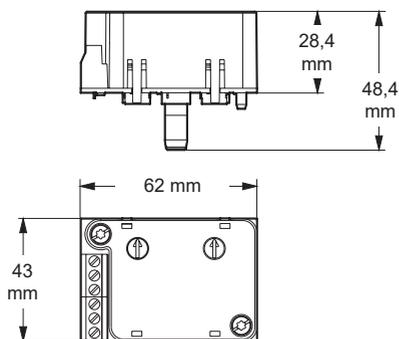


Fig. 3

	T15
	1
	3
	s24 (1x)

Fig. 4

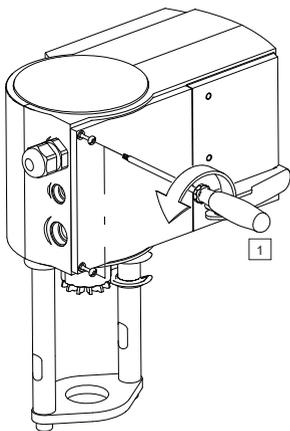


Fig. 5

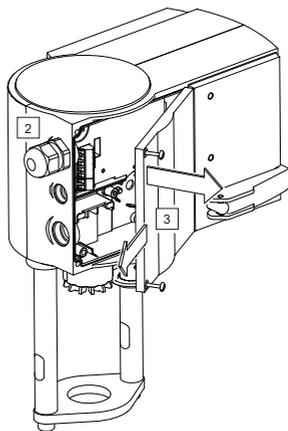


Fig. 6

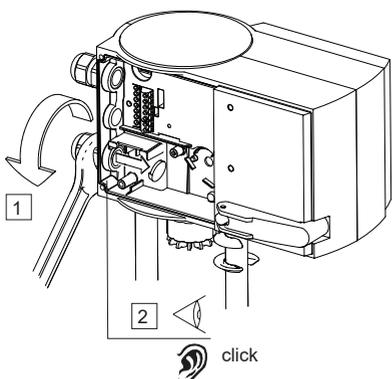


Fig. 7

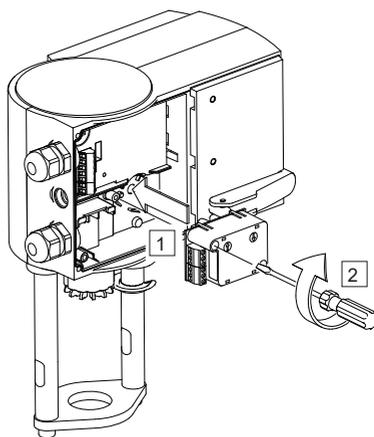


Fig. 8

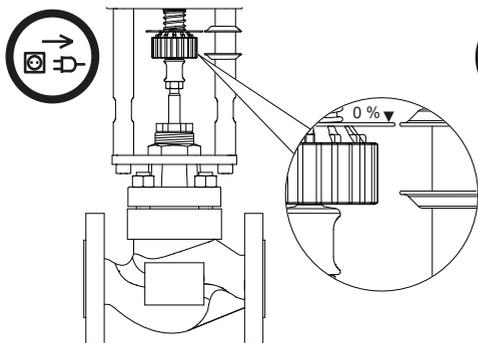


Fig. 9a

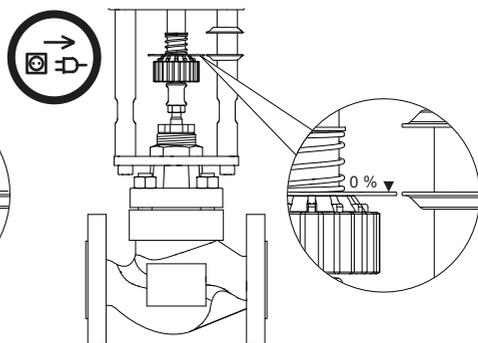


Fig. 9b

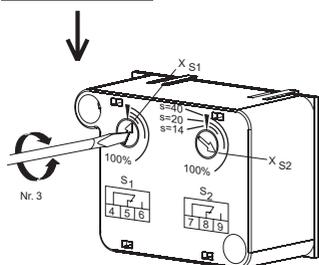


Fig. 10a

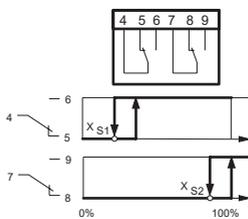


Fig. 10b

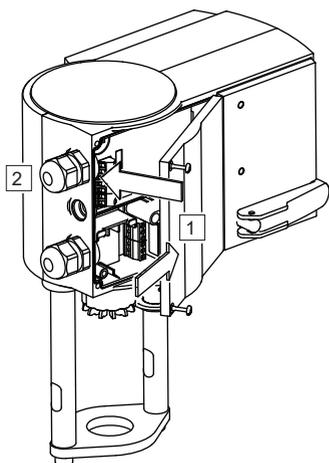


Fig. 11


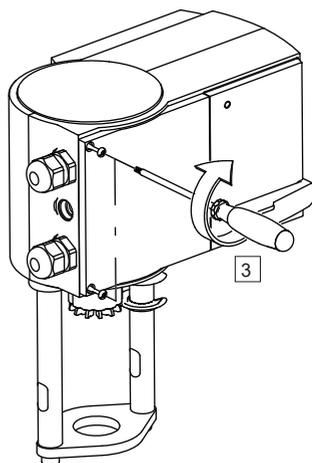


Fig. 12

Interruttori ausiliari per attuatori elettrici AEL3

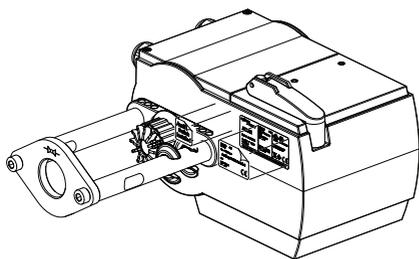

spirax/sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V	 238A E7624 23FR A7F2348F232U Temperature Indicating & Regulating Equipment	
	Equipment intended for connection to a Class 2 power source.	 	

spirax/sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	---	------------------

24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
---	------------------

Nota: L'etichetta sovrapposta è obbligatoria per la variante 24 V perché l'interruttore di fine corsa è privo della certificazione UL.

Auxiliary Switch Installed

spirax/sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	24 Vac/dc 12W 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	---	------------------

Auxiliary Switch Installed

spirax/sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	100-110 V- 28 VA 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	--	------------------

Auxiliary Switch Installed

spirax/sarco AEL3E Date Code: XXX-A Country of Origin: Germany Spirax-Sarco Limited, Charlton House, Cheltenham, Gloucestershire, GL53 9ER, GB	230 V- 28 VA 50/60Hz max. -10T55 (60)°C IP68 Control Signal: DC 0...10V Pollution Deg. 3 Overvoltage Cat. III	
--	--	------------------

Fig. 13

Interruttori ausiliari per attuatori elettrici AEL3